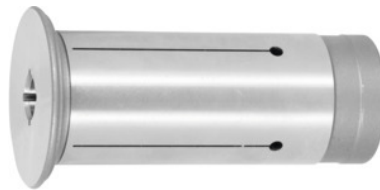


**Garant**

**Slotted reducing adapter with cooling, Ø 32 mm, Clamping range Ø D1: 6mm**


**Order data**

Order number	302175 6
GTIN	4045197763242
Item class	31G

**Description**
**Version:**

**With cooling channel slots.**

**Application:**

- **For drilling, reaming, milling, and tool sharpening.**
- **Very high flexibility due to reduction in clamping diameter.**
- **Very high torque guarantees a higher volume of metal removal compared to direct clamping.**
- **Concentricity  $\pm 5 \mu\text{m}$  (system accuracy at  $3 \times D$ ).**
- **Concentricity  $\pm 2 \mu\text{m}$  (for reducing adapter).**
- **Can be used in all commercially available hydraulic chucks.**

**Suitable for:**

Hydraulic chuck **with clamping Ø 32 mm.**

**Technical description**

Overall length L	63.5 mm
Ø D	32 mm
Clamping Ø D <sub>1</sub>	6 mm
Product name attribute	Ø 32 mm
Concentricity system	5 $\mu\text{m}$
Type of product	Reducing adapter

