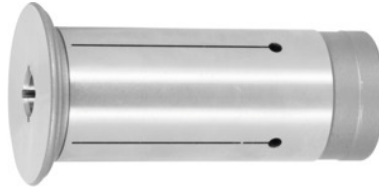


Garant**Slotted reducing adapter with cooling, Ø 32 mm, Clamping range Ø D1: 18mm****Order data**

Order number	302175 18
GTIN	4045197763303
Item class	31G

Description**Version:**

With cooling channel slots.

Application:

- For drilling, reaming, milling, and tool sharpening.
- Very high flexibility due to reduction in clamping diameter.
- Very high torque guarantees a higher volume of metal removal compared to direct clamping.
- Concentricity $\pm 5 \mu\text{m}$ (system accuracy at $3 \times D$).
- Concentricity $\pm 2 \mu\text{m}$ (for reducing adapter).
- Can be used in all commercially available hydraulic chucks.

Suitable for:

Hydraulic chuck with clamping Ø 32 mm.

Technical description

Clamping Ø D ₁	18 mm
Ø D	32 mm
Overall length L	63.5 mm
Product name attribute	Ø 32 mm
Concentricity system	5 µm

Type of product

Reducing adapter