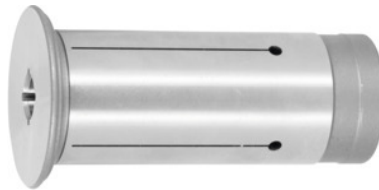


**Garant**
**Slotted reducing adapter with cooling, Ø 32 mm, Clamping range Ø D1: 20mm**

**Order data**

Order number	302175 20
GTIN	4045197763310
Item class	31G

**Description**
**Version:**

**With cooling channel slots.**

**Application:**

- For drilling, reaming, milling, and tool sharpening.
- Very high flexibility due to reduction in clamping diameter.
- Very high torque guarantees a higher volume of metal removal compared to direct clamping.
- Concentricity  $\pm 5 \mu\text{m}$  (system accuracy at  $3 \times D$ ).
- Concentricity  $\pm 2 \mu\text{m}$  (for reducing adapter).
- Can be used in all commercially available hydraulic chucks.

**Suitable for:**

Hydraulic chuck with clamping Ø 32 mm.

**Technical description**

Ø D	32 mm
Clamping Ø D <sub>1</sub>	20 mm
Overall length L	63.5 mm
Product name attribute	Ø 32 mm
Concentricity system	5 µm

Type of product

Reducing adapter