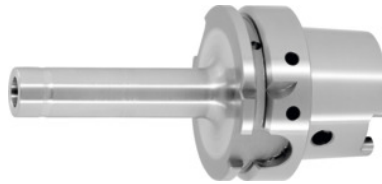


**Garant**
**Arbor for screw-in milling cutters with thread cylindrical form, HSK-A 63,  
Thread M × Length L1: M8X100**

**Order data**

Order number	307042 M8X100
GTIN	4045197764355
Item class	31A

**Description**
**Version:**

Plain design.

With Balluff/RFID chip bore.

**Application:**

To take screw-in milling cutters with thread.

**Optional extras:**

Extensions No. 301358, reducers No. 301359, coolant pipe No. 309880, socket for coolant pipe No. 309890.

**Note:**

Solid carbide arbors and extensions for screw-in milling cutters No. 301374 – 301379 and No. 301361 – 301368.

**Technical description**

Bore $\varnothing D_1$	8.5 mm
$L_2$	5 mm
Reach $L_1$	100 mm
$\varnothing D_2$	13 mm
Thread M	M8×100
Overhang dimension A	126 mm

Adapter	HSK-A 63
Arbor standard	DIN 69893
Arbor standard	ISO 12164-1
Shape	A
Balance quality G at rotational speed	G 2.5 at 25,000 rpm
Concentricity	$\leq 3 \mu\text{m}$
Machining strategy	HSC
Type of product	Threaded copy mill arbor