




## Horizontal toggle clamp for removable handle, with horizontal base, Type: 2

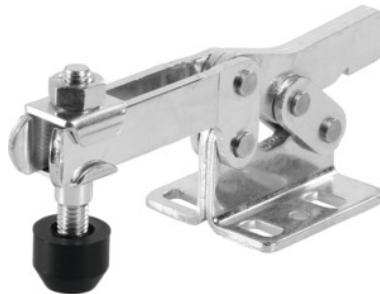

### Order data

Order number	376617 2
GTIN	4020772093945
Item class	35A

### Description

#### Version:

Captive contact screws.

Can be used only in conjunction with No. 376627.

With horizontal base for fixing to base plates etc.

#### Advantage:

Interference contours are eliminated simply by removing the handle.

#### Application:

**For quick clamping and releasing of parts in series production** or for installation as part of special clamping jigs. Suitable for clamping during drilling, reaming, grinding, bending, welding, fitting etc.

Hole spacing e: 26 mm

Hole spacing f: 24.5 mm

Bore  $\varnothing$  d: 5.6 mm

Clamping height  $L_2$ : 24 mm

Clamping force P1: 1000 N

Clamping force P2: 1200 N

### Technical description

Clamping force P1	1000 N
-------------------	--------

Clamping force P2	1200 N
Hole spacing e	26 mm
overall height	45 mm
overall length	113 mm
Clamping height L <sub>2</sub>	24 mm
Bore Ø d	5.6 mm
Hole spacing f	24.5 mm
Contact screw	M6×35 mm
Type	6837M
Type of product	Quick clamp