


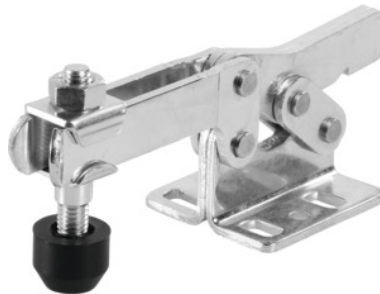

Horizontal toggle clamp for removable handle, with horizontal base, Type: 3



Order data

Order number	376617 3
GTIN	4020772094201
Item class	35A

Description

Version:

Captive contact screws.

Can be used only in conjunction with No. 376627.

With horizontal base for fixing to base plates etc.

Advantage:

Interference contours are eliminated simply by removing the handle.

Application:

For quick clamping and releasing of parts in series production or for installation as part of special clamping jigs. Suitable for clamping during drilling, reaming, grinding, bending, welding, fitting etc.

Hole spacing e: 25.7 mm

Hole spacing f: 25 mm

Bore \varnothing d: 6.5 mm

Clamping height L_2 : 32 mm

Clamping force P1: 1800 N

Clamping force P2: 2500 N

Technical description

Clamping force P2	2500 N
-------------------	--------

overall length	134 mm
Contact screw	M8×45 mm
Clamping force P1	1800 N
Clamping height L ₂	32 mm
Hole spacing e	25.7 mm
overall height	48.5 mm
Bore Ø d	6.5 mm
Hole spacing f	25 mm
Type	6837M
Type of product	Quick clamp