




## Horizontal toggle clamp for removable handle, with horizontal base, Type: 4

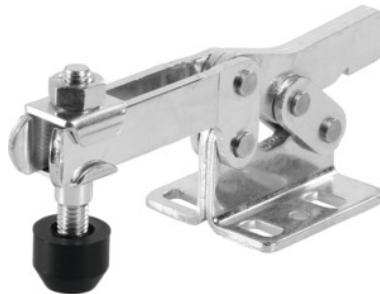

### Order data

|              |               |
|--------------|---------------|
| Order number | 376617 4      |
| GTIN         | 4020772094263 |
| Item class   | 35A           |

### Description

#### Version:

Captive contact screws.

Can be used only in conjunction with No. 376627.

With horizontal base for fixing to base plates etc.

#### Advantage:

Interference contours are eliminated simply by removing the handle.

#### Application:

**For quick clamping and releasing of parts in series production** or for installation as part of special clamping jigs. Suitable for clamping during drilling, reaming, grinding, bending, welding, fitting etc.

Hole spacing e: 41 mm

Hole spacing f: 36 mm

Bore  $\varnothing$  d: 8.5 mm

Clamping height  $L_2$ : 45 mm

Clamping force P1: 2000 N

Clamping force P2: 3000 N

### Technical description

|                |        |
|----------------|--------|
| overall length | 191 mm |
|----------------|--------|

|                                |             |
|--------------------------------|-------------|
| Clamping force P2              | 3000 N      |
| Clamping force P1              | 2000 N      |
| Hole spacing f                 | 36 mm       |
| Clamping height L <sub>2</sub> | 45 mm       |
| Bore Ø d                       | 8.5 mm      |
| Hole spacing e                 | 41 mm       |
| overall height                 | 75 mm       |
| Contact screw                  | M8×65 mm    |
| Type                           | 6837M       |
| Type of product                | Quick clamp |