


LESSMANN®
THE GERMAN BRUSH COMPANY

Wheel brush with shank micro-abrasive SiC 320 grit, Brush Ø D1× bristle width L1: 30X6mm

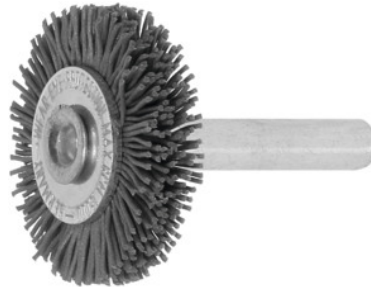

Order data

Order number	574450 30X6
GTIN	4017359111352
Item class	57L

Description

Version:

Abrasive nylon strands with silicon carbide, crimped into steel sleeve; **shank Ø 6 mm.**

Application:

For portable grinders, on flexible drive machines or drills for brushing surfaces. High speeds improve the brush performance.

Wet and dry fine rubbing down of aluminium, steel, stainless steel and plastics. Maximum operating temperature 80 °C.

Technical description

Brush Ø D ₁	30 mm
Length of brush section H ₁	6 mm
maximum speed	15000 min ⁻¹
recommended speed	6000 min ⁻¹
Shank Ø D _s	6 mm
Grinding medium code	SiC
Type of product	Wheel brush

