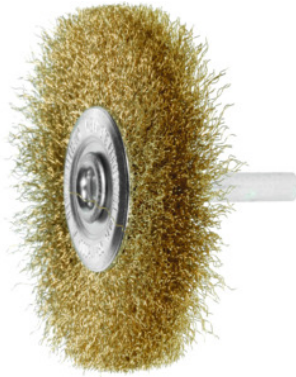


LESSMANN®
THE GERMAN BRUSH COMPANY**Wheel brush with shank Brass wire 0.20 mm., Brush Ø D1× bristle width L1:
70X10mm****Order data**

Order number	574350 70X10
GTIN	4017359082805
Item class	57L

Description**Version:**

Waved special high quality wire, **shank Ø 6 mm.**

Application:

For portable grinders, on flexible drive machines or drills for brushing surfaces. High speeds improve the brush performance.

For heavy-duty deburring and brushing of non-ferrous metals

Technical description

Length of brush section H ₁	19 mm
Brush Ø D ₁	70 mm
Bristle thickness	0.2 mm
maximum speed	15000 min ⁻¹
Bristle width L ₁	8 mm
Shank Ø D _s	6 mm

Brush material	Brass wire
Twisted knotting	waved
Type of product	Wheel brush