


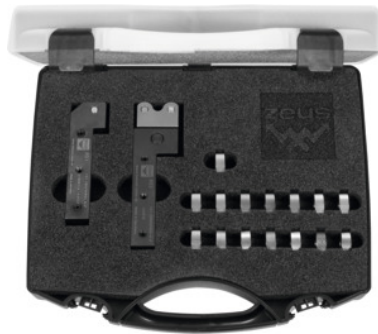

Knurl forming tool set, Shank / insert size: 20mm



Order data

Order number	290025 20
GTIN	4030741656859
Item class	29H

Description

Content:

1 pc. each knurl forming tool No. 290000 and No. 290010: Size 20

3 pc. each knurl No. 290161: Size 20×8/0.8; 20×8/1.0; 20×8/1.5

1 pc. each knurl No. 290176 and No. 290181: Size 20×8/0.8; 20×8/1.0; 20×8/1.5

Technical description

Cutting direction	left-hand and right-hand
for knurl profile	RBL 2×BR
for knurl profile	RBR 2×BL
for knurl profile	RBL 1×BR
for knurl profile	RAA 2×AA
for knurl profile	RBR 1×BL
for knurl profile	RGV30° 1×GE30°
for knurl profile	RGE30° 1×GV30°
for knurl profile	RBL 1×BR

for knurl profile	RGE30° BL/BR30°
for knurl profile	RGE45° BL/BR45°
Type of product	Self-centering knurling tool

Accessories

Knurl PM Knurl \varnothing d1 \times knurl width b / pitch 20X8/0,8 mm	290181 20X8/0,8
Knurl forming tooluniversal Shank size 20 mm	290010 20
Knurl PM Knurl \varnothing d1 \times knurl width b / pitch 20X8/1,0 mm	290176 20X8/1,0
Knurl PM Knurl \varnothing d1 \times knurl width b / pitch 20X8/1,6 mm	290161 20X8/1,6
Knurl PM Knurl \varnothing d1 \times knurl width b / pitch 20X8/1,5 mm	290176 20X8/1,5
Knurl PM Knurl \varnothing d1 \times knurl width b / pitch 20X8/1,6 mm	290176 20X8/1,6
Knurl PM Knurl \varnothing d1 \times knurl width b / pitch 20X8/1,0 mm	290161 20X8/1,0
Knurl PM Knurl \varnothing d1 \times knurl width b / pitch 20X8/1,6 mm	290181 20X8/1,6
Knurl PM Knurl \varnothing d1 \times knurl width b / pitch 20X8/1,0 mm	290181 20X8/1,0
Knurl PM Knurl \varnothing d1 \times knurl width b / pitch 20X8/0,8 mm	290176 20X8/0,8
Knurl PM Knurl \varnothing d1 \times knurl width b / pitch 20X8/1,5 mm	290181 20X8/1,5
Knurl PM Knurl \varnothing d1 \times knurl width b / pitch 20X8/1,5 mm	290161 20X8/1,5
Knurl PM Knurl \varnothing d1 \times knurl width b / pitch 20X8/0,8 mm	290161 20X8/0,8