




Permanent magnet clamping block, with fine pole distribution, Type: MH203

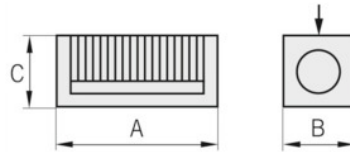

Order data

Order number	380815 MH203
GTIN	2050001854261
Item class	33S

Description

Version:

Two magnetic clamping faces.

Application:

For profiling and machining small workpieces such as punches etc.

Note:

Permanent magnet, not switchable.

Technical description

maximum angular deviation	5 degrees
Magnetic field height	6 mm
Nominal clamping force	80 N/cm ²
Width B	25 mm
Type	MH203
Weight	0.5 kg
Grinding allowance in pole area	6 mm
Pole pitch	4 mm
Overall height C	25 mm
Length A	100 mm

Type of product

Magnetic clamping plate