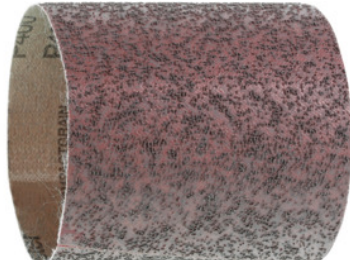


**Mini-linishing belt Ø 90×100 mm, KK770J, Grit: 120****Order data**

Order number	568556 120
GTIN	4018875293423
Item class	56V

Description**Version:**

Compact grit is a composite of many different individual aluminium oxide grit particles. Continual exposure of fresh abrasive grit achieves **consistent grinding results** and long service life. For **fine grinding of high-alloy steels, chrome-nickel steels, titanium alloys etc.** Mini linishing belts Ø 90×100 mm (289×100 mm).

Application:

For use on surface grinding and burnishing machines with backing rollers No. 568570 – 568577 (mounting bore Ø 19 mm). Maximum speed 5000 rpm.
Open grit distribution requires only slight applied pressure, even wear.

Technical description

Grit	120
Linishing belt width	100 mm
Linishing belt Ø	90 mm
Grinding media	Aluminium oxide
Grinding medium code	A
Iron, sulphur and chlorine constituents	< 0.1 %

Manufacturer's designation	KK770J
Propulsive equipment	Burnishing machine
maximum speed	5000 min ⁻¹
Type of product	Linishing belt

User data

	Suitability	V _c	ISO code
Alu Mg	suitable only under restricted conditions		
Steel < 1400 N/mm ²	suitable		
Steel < 55 HRC	suitable		
Steel < 60 HRC	suitable		
Steel < 67 HRC	suitable		
INOX	suitable		
Ti	suitable		
CuZn	suitable only under restricted conditions		
Paint	suitable		
dry	suitable		

Accessories

Backing roller Ø 90×100 mm Type AIR	568575 AIR
-------------------------------------	------------