


## Boring bar head for radial turrets, Type B H = 120, Clamping $\varnothing$ : 12 mm

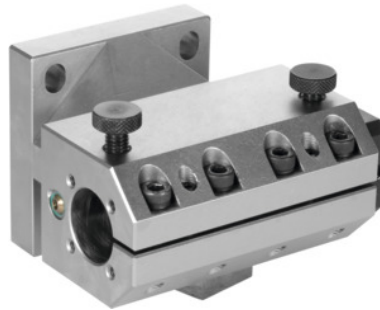

### Order data

Order number	319173 12
GTIN	4251414900592
Item class	38T

### Description

#### Version:

The first successful introduction of a tool mounting design which can be used on both disc turrets and radial turrets. Irrespective of the alignment method in use.

Modular system configuration.

#### Advantage:

- **All tools with direct internal coolant supply connection.**
- **Cost reduction via efficient stock-holding of bearings.**
- **Higher productivity due to improved positioning.**

#### Application:

Can be inserted by changing over the locking cover.

#### Note:

Suitable for vibration-damped boring bars No. 264902 – 264908, No. 264910 – 264922 or tools with plain shank (such as: solid carbide boring bars  $\varnothing$  10 mm).

Length L: 70 mm

### Technical description

Clamping $\varnothing$	12 mm
Length L	70 mm
Adapter	Type B H = 120

