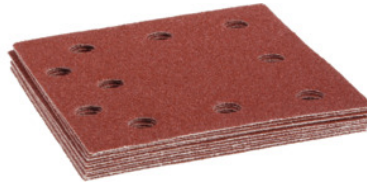


**Abrasive paper pack, 10 pieces 10 holes, Grit: 60****Order data**

Order number	557620 60
GTIN	4058546476304
Item class	56Z

**Description****Version:**

Tough elasticated paper spread with Aluminium Oxide. Very high metal removal rate  
Rear face with hook and loop fastener attachment for quick change of sheets.

**Application:**

Grinding of metal and hardwood.

Special perforation system for orbital sander No. 077326 SPS140.

**Technical description**

Grit	60
Grit designation	coarse
Width	115 mm
Length	107 mm
Number of dust extraction holes	10
Number of abrasive sheets	10
Type of product	Hook-and-loop sandpaper

**User data**

	Suitability	V <sub>c</sub>	ISO code
--	-------------	----------------	----------

Alu Mg	suitable
Steel < 900 N/mm <sup>2</sup>	suitable
Steel < 1400 N/mm <sup>2</sup>	suitable
Steel < 55 HRC	suitable
Steel < 60 HRC	suitable
Steel < 67 HRC	suitable
INOX	suitable only under restricted conditions
wet maximum	suitable only under restricted conditions
dry	suitable