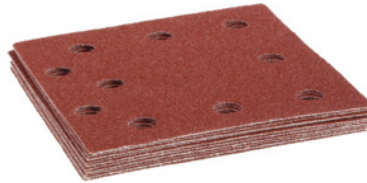


Abrasive paper pack, 10 pieces 10 holes, Grit: 80**Order data**

Order number	557620 80
GTIN	4002395384778
Item class	56Z

Description**Version:**

Tough elasticated paper spread with Aluminium Oxide. Very high metal removal rate
Rear face with hook and loop fastener attachment for quick change of sheets.

Application:

Grinding of metal and hardwood.

Special perforation system for orbital sander No. 077326 SPS140.

Technical description

Grit designation	coarse
Grit	80
Width	115 mm
Length	107 mm
Number of dust extraction holes	10
Number of abrasive sheets	10
Type of product	Hook-and-loop sandpaper

User data

	Suitability	V _c	ISO code
--	-------------	----------------	----------

Alu Mg	suitable
Steel < 900 N/mm ²	suitable
Steel < 1400 N/mm ²	suitable
Steel < 55 HRC	suitable
Steel < 60 HRC	suitable
Steel < 67 HRC	suitable
INOX	suitable only under restricted conditions
wet maximum	suitable only under restricted conditions
dry	suitable