


Abrasive paper pack, 10 pieces 10 holes, Grit: 240

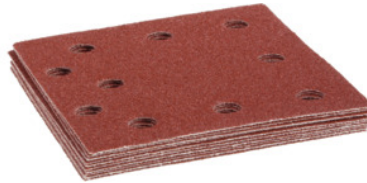

Order data

| | |
|--------------|---------------|
| Order number | 557620 240 |
| GTIN | 4058546476335 |
| Item class | 56Z |

Description

Version:

Tough elasticated paper spread with Aluminium Oxide. Very high metal removal rate
Rear face with hook and loop fastener attachment for quick change of sheets.

Application:

Grinding of metal and hardwood.

Special perforation system for orbital sander No. 077326 SPS140.

Technical description

| | |
|---------------------------------|-------------------------|
| Grit designation | fine |
| Grit | 240 |
| Width | 115 mm |
| Length | 107 mm |
| Number of dust extraction holes | 10 |
| Number of abrasive sheets | 10 |
| Type of product | Hook-and-loop sandpaper |

User data

| | Suitability | V _c | ISO code |
|--|-------------|----------------|----------|
|--|-------------|----------------|----------|

| | |
|--------------------------------|---|
| Alu Mg | suitable |
| Steel < 900 N/mm ² | suitable |
| Steel < 1400 N/mm ² | suitable |
| Steel < 55 HRC | suitable |
| Steel < 60 HRC | suitable |
| Steel < 67 HRC | suitable |
| INOX | suitable only under restricted conditions |
| wet maximum | suitable only under restricted conditions |
| dry | suitable |