


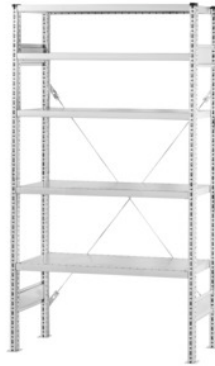

Storage shelf, basic rack, Depth 500 mm, Height /storage shelf width: 1910/1300mm



Order data

Order number	990462 1910/1300
GTIN	4052941784774
Item class	95S

Description

Version:

Storage shelf racking in two bay widths, 994 mm and 1282 mm. Completely galvanised with 5 storage shelves, adjustable in intervals of 53 mm. Welded profiles and floors. No tools required for assembly; can be expanded without any problems. Separate rack stiles allow transport optimisation.

Load per bay: 1900 kg per bay.

Description:

Assembled size:

Basic rack: Nominal length 1300 mm + 44 mm

Extension rack: Nominal length 1300 mm + 13 mm

Note:

- **Floor and wall fastenings are not included.**
- **Access from one side only due to use of diagonal braces.**
- **The free unsupported length (K) must not be more than 595 mm.**
- **Delivered unassembled.**
- **Transport optimised – sent in 2 postal packages, no sending with pallets.**

Material: galvanized

Shelf load capacity / maximum distributed shelf load (on metal): 150 kg

Height: 1910 mm

Assembled size basic rack width: 1344 mm
Storage shelf clear width: 1282 mm
Load capacity of each loose shelf: 150 kg

Technical description

Plug-in assembly	yes
Storage shelf clear width	1282 mm
Customer assembly	yes
Rack installation	Basic rack
Height	1910 mm
Assembled size basic rack width	1344 mm
Load capacity of each loose shelf	150 kg
Shelf load capacity / maximum distributed shelf load (on metal)	150 kg
Shelf thickness	40 mm
Height adjustment interval	53 mm
Type of installation	Plug-in racking
Material	galvanized
Product name attribute	Depth 500 mm
Type of product	Storage shelf