


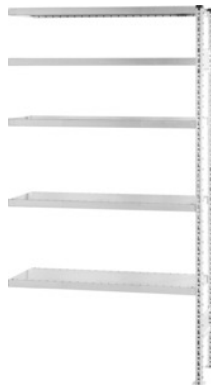

Storage shelf, add-on rack, Depth 500 mm, Height /storage shelf width: 1910/1300mm



Order data

Order number	990463 1910/1300
GTIN	4052941784958
Item class	95S

Description

Version:

Storage shelf racking in two bay widths, 994 mm and 1282 mm. Completely galvanized with 5 storage shelves, adjustable in intervals of 53 mm. Welded profiles and floors. No tools required for assembly; can be expanded without any problems. Separate rack stiles allow transport optimisation.

Load per bay: 1900 kg per bay.

Description:

Assembled size:

Basic rack: Nominal length 1300 mm + 44 mm

Extension rack: Nominal length 1300 mm + 13 mm

Note:

- **Floor and wall fastenings are not included.**
- **Access from one side only due to use of diagonal braces.**
- **The free unsupported length (K) must not be more than 595 mm.**
- **Delivered unassembled.**
- **Transport optimised – sent in 2 postal packages, no sending with pallets.**

Material: galvanized

Shelf load capacity / maximum distributed shelf load (on metal): 150 kg

Height: 1910 mm

Assembled size add-on rack width: 1313 mm

Storage shelf clear width: 1282 mm

Load capacity of each loose shelf: 150 kg

Technical description

Customer assembly	yes
Storage shelf clear width	1282 mm
Plug-in assembly	yes
Height	1910 mm
Rack installation	Extension rack
Assembled size add-on rack width	1313 mm
Load capacity of each loose shelf	150 kg
Shelf load capacity / maximum distributed shelf load (on metal)	150 kg
Shelf thickness	40 mm
Height adjustment interval	53 mm
Type of installation	Plug-in racking
Material	galvanized
Product name attribute	Depth 500 mm
Type of product	Storage shelf