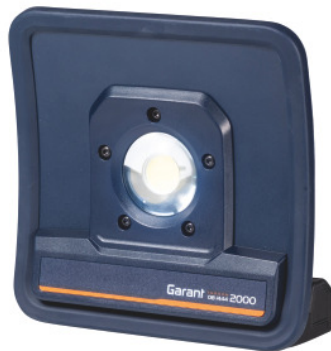


Garant**Cordless LED floodlight, Type: 2000****Order data**

Order number	081444 2000
GTIN	4062406232887
Item class	01A

Description**Version:**

Cordless LED battery floodlight with sturdy aluminium casing for everyday use in rough environments.

- **High-performance COB LED modules.**
- **Dimmable in 5 steps from 10 to 100 %.**
- **Practical monitoring of the state of charge of the battery by LED display directly on the lamp.**
- **Base with integral 10 mm hole, for mounting on suitable stands.**

Function:

IP67: Protected against intermittent immersion in water and protected against penetration by dust (dust-tight), also completely protected against touching.

Supplied with:

Supplied with USB charging cable and plug-in power supply unit.

Technical description

ATEX zone	no
Type of rechargeable battery	Lithium-ion

IP Index of Protection	IP 67
Battery voltage	7.3 V
Illumination time	2 - 20 h
Bulb	LED module
Overall height	163 mm
Overall length	163 mm
Overall width	63 mm
Power supply	Rechargeable battery-powered
Number of rechargeable batteries contained	1
Battery capacity	4 Ah
Weight	790 g
Illumination	200 - 2000 lm
Type of product	Floodlight

Accessories

Cordless lamp spare parts Type 3	081434 3
Cordless lamp spare parts Type 4	081434 4
Li-ion battery Battery capacity 4000 mAh	081431 4000
USB charger Type CABLE	081455 CABLE
USB charger Type CHARGER	081455 CHARGER
Spare lens with seal Type 1	081454 1