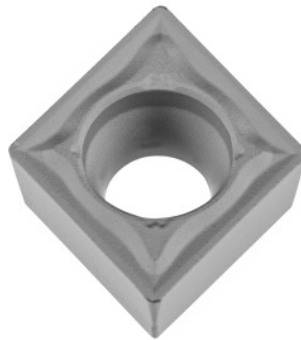


**CCMT 09T304, Grade: HBT020****Order data**

Order number	260211 HBT020
GTIN	4062406256999
Item class	22D

Description

CCMT 09T304 HBT020 Grade: HBT020
Chip breaker: PM
Cutting depth a_p : 0.5 - 2.5 mm
Feed f : 0.12 - 0.3 mm/rev.
Cutting speed v_c main application: 100 - 280 m/min

Technical description

Chip breaker	PM
Coating	TiCN
Number of changes/inserts	2
ISO code indexable insert	CCMT 09T304
Cutting speed v_c main application	100 - 280 m/min
Cutting depth a_p	0.5 - 2.5 mm
Feed f	0.12 - 0.3 mm/rev.

Main application	P
Cutting conditions	slightly interrupted
Corner radius	0.4 mm
Finishing/roughing assignment	Skrubbearbejdning-sletbearbejdning
Tool material	Carbide
Grade	HBT020
Type of product	Indexable insert for turning