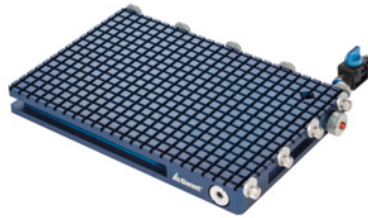


Garant
Grid vacuum plate Venturi system, Type: VR1

Order data

Order number	384900 VR1
GTIN	4062406256432
Item class	31E

Description
Version:

Aluminium, steel blue anodised. Operating pressure 3.5 – 8 bar. The final vacuum is approx. 80 mbar (92 % vacuum). Integral noise muffler reduces the noise generation. Height tolerance ± 0.5 mm. Supplied with 2 ZeroClamp holes, 12M10, pitch 200 mm.

Advantage:

Low-cost entry-level system. Low maintenance costs. Ready for immediate use. Can quickly and easily be converted to **vacuum pump operation**.

Application:

For vacuum clamping **without** a vacuum pump.

Supplied with:

Back-stop discs, compressed air hose \varnothing 10 mm (1 m), Venturi nozzle (1 pc.).

Sealing cord \varnothing 4 mm (10 m). Hose adaptor (1x), plug LW 12 (1x), stepless adjustable clamps (2x).

Note:

When using Venturi nozzles, we advise against machining using coolant emulsion.

Technical description

Length	300 mm
Height	32.5 mm
Width	200 mm
Intervals	12.5 mm

Version	Zero-point clamping system
Type of product	Vacuum clamping plate