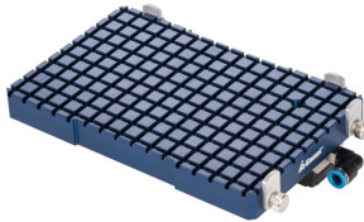


**Garant**
**Grid vacuum plate Venturi system, Type: VRV0**

**Order data**

Order number	384900 VRV0
GTIN	4062406256425
Item class	31E

**Description**
**Version:**

Aluminium, steel blue anodised. Operating pressure 3.5 – 8 bar. The final vacuum is approx. 80 mbar (92 % vacuum). Integral noise muffler reduces the noise generation. Height tolerance  $\pm 0.5$  mm.

**Advantage:**

**Low-cost entry-level system.** Low maintenance costs. Ready for immediate use.

**Application:**

For vacuum clamping **without** a vacuum pump. For use on **machine vices**. Especially thin components can be clamped flexibly and with little trouble.

**Supplied with:**

Back-stop discs, compressed air hose  $\varnothing$  10 mm (1 m), Venturi nozzle (1 pc.).

Sealing cord  $\varnothing$  4 mm (10 m).

**Note:**

When using Venturi nozzles, we advise against machining using coolant emulsion.

**Technical description**

Length	200 mm
Intervals	12.5 mm
Width	125 mm
Height	21 mm

Type of product

Vacuum clamping plate