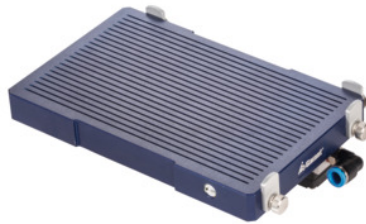


Garant**Slit vacuum plate Venturi system, Type: VSV0****Order data**

Order number	384905 VSV0
GTIN	4062406256449
Item class	31E

Description**Version:**

Aluminium, steel blue anodised. Operating pressure 3.5 – 8 bar. The final vacuum is approx. 80 mbar (92 % vacuum). Integral noise muffler reduces the noise generation. Height tolerance ± 0.5 mm.

Advantage:

Low-cost entry-level system. Low maintenance costs. Ready for immediate use.

Application:

For vacuum clamping **without** a vacuum pump. For use on **machine vices**. Especially thin components can be clamped flexibly and with little trouble.

Supplied with:

Back-stop discs, compressed air hose $\varnothing 10$ mm (1 m), Venturi nozzle (1 pc.).

Rubber adapter mat (1x).

Note:

When using Venturi nozzles, we advise against machining using coolant emulsion.

Technical description

Width	125 mm
Length	200 mm
Height	21 mm
Type of product	Vacuum clamping plate

