


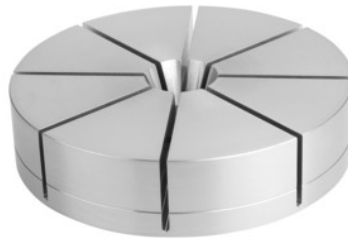

Collet mechanical Internal clamping, External Ø D: 90 mm



Order data

Order number	370127 90
GTIN	4059245292592
Item class	37K

Description

Version:

- For clamping workpieces with complex contours for 5-face machining.
- Minimum clamping depth of 2 mm.
- Clamping stroke 0.3 mm.

Material:

High-tensile aluminium.

Supplied with:

Clamping ring for machining.

Note:

For internal clamping the pull cone No. 370128 is required (see spare parts list).

Height H: 30 mm

Maximum machining depth T: 15 mm

Technical description

Version	Internal clamping
Maximum machining depth T	15 mm
Height H	30 mm
Clamping range	0.3 mm
Type of product	Clamping head

Accessories

Adapter for mechanical collet External Ø D 90 mm

370125 90

Pull cone Type 90

370128 90