


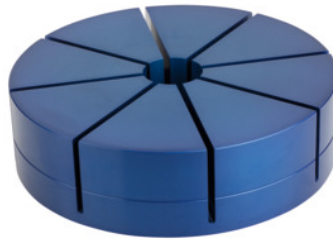

## Collet mechanical External clamping, External Ø D: 160mm



### Order data

Order number	370126 160
GTIN	4059245292578
Item class	37K

### Description

**Version:**

- For clamping workpieces with complex contours for 5-face machining.
- Minimum clamping depth of 2 mm.
- Clamping stroke 0.3 mm.

**Material:**

High-tensile aluminium.

**Supplied with:**

Clamping ring for machining.

### Technical description

Version	External clamping
Maximum machining depth T	25 mm
Height H	45 mm
Clamping range	0.3 mm
Type of product	Collet

## Accessories

Adapter for mechanical collet External Ø D 160 mm

370125 160