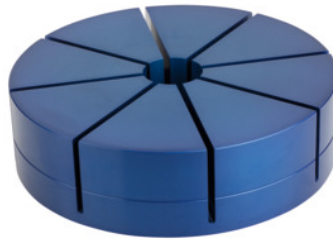


**Collet mechanical External clamping, External Ø D: 65mm****Order data**

Order number	370126 65
GTIN	4059245292547
Item class	37K

**Description****Version:**

- For clamping workpieces with complex contours for 5-face machining.
- Minimum clamping depth of 2 mm.
- Clamping stroke 0.3 mm.

**Material:**

High-tensile aluminium.

**Supplied with:**

Clamping ring for machining.

**Technical description**

Version	External clamping
Height H	25 mm
Maximum machining depth T	10 mm
Clamping range	0.3 mm
Type of product	Collet

## Accessories

Adapter for mechanical collet External Ø D 65 mm

370125 65