


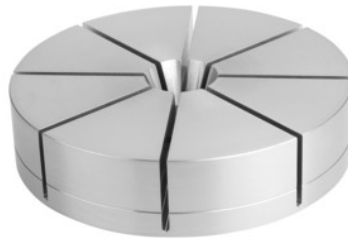

## Collet mechanical Internal clamping, External Ø D: 160 mm



### Order data

Order number	370127 160
GTIN	4059245292615
Item class	37K

### Description

#### Version:

- For clamping workpieces with complex contours for 5-face machining.
- Minimum clamping depth of 2 mm.
- Clamping stroke 0.3 mm.

#### Material:

High-tensile aluminium.

#### Supplied with:

Clamping ring for machining.

#### Note:

For internal clamping the pull cone No. 370128 is required (see spare parts list).

Height H: 40 mm

Maximum machining depth T: 25 mm

### Technical description

Version	Internal clamping
Height H	40 mm
Maximum machining depth T	25 mm
Clamping range	0.3 mm
Type of product	Clamping head

---

## Accessories

Pull cone Type 160

370128 160

Adapter for mechanical collet External Ø D 160 mm

370125 160