


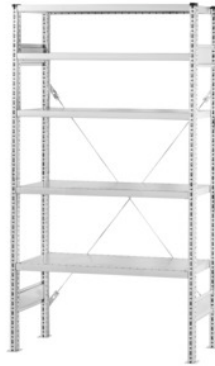

Storage shelf, basic rack, Depth 400 mm, Height /storage shelf width: 2281/1300mm



Order data

| | |
|--------------|------------------|
| Order number | 990460 2281/1300 |
| GTIN | 4052941784798 |
| Item class | 95S |

Description

Version:

Storage shelf racking in two bay widths, 994 mm and 1282 mm. Completely galvanised with 5 storage shelves, adjustable in intervals of 53 mm. Welded profiles and floors. No tools required for assembly; can be expanded without any problems. Separate rack stiles allow transport optimisation.

Load per bay: 1900 kg per bay.

Description:

Assembled size:

Basic rack: Nominal length 1300 mm + 44 mm

Extension rack: Nominal length 1300 mm + 13 mm

Note:

- **Floor and wall fastenings are not included.**
- **Access from one side only due to use of diagonal braces.**
- **The free unsupported length (K) must not be more than 595 mm.**
- **Delivered unassembled.**
- **Transport optimised – sent in 2 postal packages, no sending with pallets.**

Material: galvanized

Shelf load capacity / maximum distributed shelf load (on metal): 150 kg

Height: 2281 mm

Assembled size basic rack width: 1344 mm
Storage shelf clear width: 1282 mm
Load capacity of each loose shelf: 150 kg

Technical description

| | |
|---|-----------------|
| Shelf load capacity / maximum distributed shelf load (on metal) | 150 kg |
| Storage shelf clear width | 1282 mm |
| Height | 2281 mm |
| Load capacity of each loose shelf | 150 kg |
| Assembled size basic rack width | 1344 mm |
| Shelf thickness | 40 mm |
| Height adjustment interval | 53 mm |
| Type of installation | Plug-in racking |
| Material | galvanized |
| Product name attribute | Depth 400 mm |
| Type of product | Storage shelf |