


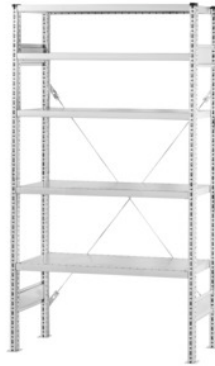

Storage shelf, basic rack, Depth 500 mm, Height /storage shelf width: 2281/1000 mm



Order data

Order number	990462 2281/1000
GTIN	4052941784729
Item class	96P

Description

Version:

Storage shelf racking in two bay lengths, 994 mm and 1282 mm. Completely galvanised with 5 storage shelves, adjustable in intervals of 53 mm. Welded profiles and floors. No tools required for assembly; can be expanded without any problems. Separate rack stiles allow transport optimisation.

Load per bay: 1900 kg per bay.

Description:

Assembled size:

Basic rack: Nominal length 1000 mm + 56 mm

Extension rack: Nominal length 1000 mm + 25 mm

Note:

- **Floor and wall fastenings are not included.**
- **Access from one side only due to use of diagonal braces.**
- **The free unsupported length (K) must not be more than 595 mm.**
- **Delivered unassembled.**
- **Transport optimised – sent in 2 postal packages, no sending with pallets.**

Material: galvanized

Assembled size basic rack width: 1056 mm

Storage shelf clear width: 994 mm

Load capacity of each loose shelf: 100 kg

Technical description

Assembled size basic rack width	1056 mm
Storage shelf clear width	994 mm
Load capacity of each loose shelf	100 kg
Shelf thickness	40 mm
Height adjustment interval	53 mm
Type of installation	Plug-in racking
Material	galvanized
Product name attribute	Depth 500 mm
Type of product	Storage shelf