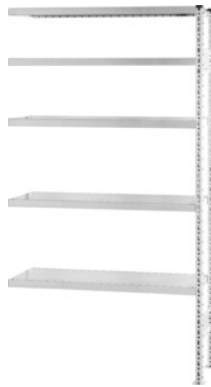


**Storage shelf, add-on rack, Depth 400 mm, Height /storage shelf width:
2281/1000mm****Order data**

Order number	990461 2281/1000
GTIN	4052941784903
Item class	95S

Description**Version:**

Storage shelf racking in two bay widths, 994 mm and 1282 mm. Completely galvanised with 5 storage shelves, adjustable in intervals of 53 mm. Welded profiles and floors. No tools required for assembly; can be expanded without any problems. Separate rack stiles allow transport optimisation.

Load per bay: 1900 kg per bay.

Description:**Assembled size:**

Basic rack: Nominal length 1000 mm + 56 mm

Extension rack: Nominal length 1000 mm + 25 mm

Note:

- **Floor and wall fastenings are not included.**
- **Access from one side only due to use of diagonal braces.**
- **The free unsupported length (K) must not be more than 595 mm.**
- **Delivered unassembled.**
- **Transport optimised – sent in 2 postal packages, no sending with pallets.**

Material: galvanized

Shelf load capacity / maximum distributed shelf load (on metal): 100 kg

Height: 2281 mm

Assembled size add-on rack width: 1025 mm
Storage shelf clear width: 994 mm
Load capacity of each loose shelf: 100 kg

Technical description

Load capacity of each loose shelf	100 kg
Storage shelf clear width	994 mm
Assembled size add-on rack width	1025 mm
Shelf load capacity / maximum distributed shelf load (on metal)	100 kg
Height	2281 mm
Shelf thickness	40 mm
Height adjustment interval	53 mm
Type of installation	Plug-in racking
Material	galvanized
Product name attribute	Depth 400 mm
Type of product	Storage shelf