


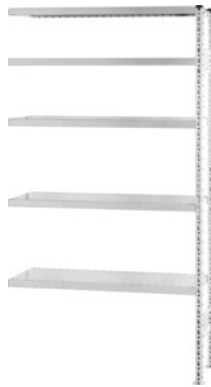

## Storage shelf, add-on rack, Depth 400 mm, Height /storage shelf width: 2281/1300mm



### Order data

Order number	990461 2281/1300
GTIN	4052941784972
Item class	95S

### Description

#### Version:

Storage shelf racking in two bay widths, 994 mm and 1282 mm. Completely galvanized with 5 storage shelves, adjustable in intervals of 53 mm. Welded profiles and floors. No tools required for assembly; can be expanded without any problems. Separate rack stiles allow transport optimisation.

**Load per bay:** 1900 kg per bay.

#### Description:

#### Assembled size:

**Basic rack:** Nominal length 1300 mm + 44 mm

**Extension rack:** Nominal length 1300 mm + 13 mm

#### Note:

- **Floor and wall fastenings are not included.**
- **Access from one side only due to use of diagonal braces.**
- **The free unsupported length (K) must not be more than 595 mm.**
- **Delivered unassembled.**
- **Transport optimised – sent in 2 postal packages, no sending with pallets.**

Material: galvanized

Shelf load capacity / maximum distributed shelf load (on metal): 150 kg

Height: 2281 mm

Assembled size add-on rack width: 1313 mm  
Storage shelf clear width: 1282 mm  
Load capacity of each loose shelf: 150 kg

---

## Technical description

Load capacity of each loose shelf	150 kg
Storage shelf clear width	1282 mm
Height	2281 mm
Shelf load capacity / maximum distributed shelf load (on metal)	150 kg
Assembled size add-on rack width	1313 mm
Shelf thickness	40 mm
Height adjustment interval	53 mm
Type of installation	Plug-in racking
Material	galvanized
Product name attribute	Depth 400 mm
Type of product	Storage shelf