


Kroepelin
Längenmesstechnik

External quick caliper with dial gauge, Measuring range: 0-10mm

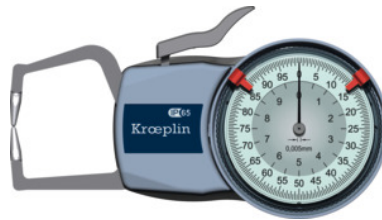

Order data

| | |
|--------------|---------------|
| Order number | 438555 0-10 |
| GTIN | 2050002040878 |
| Item class | 46Q |

Description

Version:

1 fixed and 1 movable arm with carbide spherical contact points. The deflection of the moving contact point is transmitted to the dial indicator. The measured result can be read directly.

Function:

IP65: Protected against jets of water from all directions and protected against penetration by dust (dust-tight), also completely protected against touching.

Application:

For quick measuring of external grooves, wall thicknesses, plates, pipe wall thicknesses, foils etc.

Technical description

| | |
|--|-------------------------|
| maximum contact point length L (measurement depth) | 35 mm |
| IP Index of Protection | IP 65 |
| Scale divisions | 0.005 mm |
| Measuring range | 0 - 10 mm |
| Error limit | 0.015 mm |
| Dial indicator Ø | 65 mm |
| Carbide spherical point Ø | 1.5 mm |
| Standard | Manufacturer's standard |

| | |
|------------------------|--------------------------|
| Measurement technology | analogue |
| Calibration | C7 |
| Type of product | External quick callipers |

Services

| | |
|--|----------|
| DAkkS calibration External / internal quick caliper Type S | 023460 S |
| Calibration External / internal quick caliper Type S | 023450 S |