


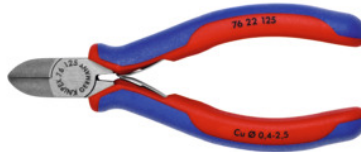

Mechanic's side cutter, polished, with grips, KW, overall length: 125mm



Order data

Order number	724205 125
GTIN	4003773048022
Item class	73F

Description

Version:

With slim head and induction hardened cutting edges. Cutter edge hardness approx. 63 HRC. Flush fitting joint with no play.

Jaws polished, handles with multi-component coating. With opening spring.

Standard:

DIN ISO 5749

Material:

Special tool steel, drop-forged and oil-hardened.

Technical description

Cutting capacity piano wire up to \varnothing	0.6 mm
Cutting capacity hard wire up to \varnothing	1 mm
Cutting capacity soft wire up to \varnothing	2.5 mm
overall length	125 mm
Product name attribute	KW
Cutting chamfer	without bevel
Standard	DIN ISO 5749
Handle	Multi-component covering

Manufacturing process	Cutting edges induction hardened (approx. 63 HRC)
Material	Special tool steel, drop-forged and oil-hardened
Surface	polished
Type of product	Cutting pliers