


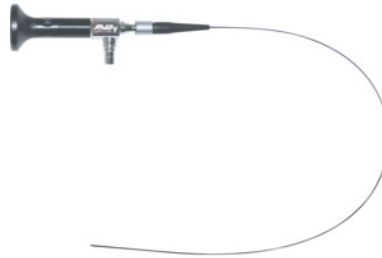

## Flexible micro-endoscope, Ø 2.4 mm, Working length (without lens): 1000mm



### Order data

Order number	492758 1000
GTIN	2050002040755
Item class	49C

### Description

#### Version:

Small diameter and flexible fibre optic design for measuring very fine components. The sturdy stainless steel tube and high-quality optics are specially well suited for rough industrial environments. Easy to connect to the required light source for the standard fibre optic cable connection (ACMI). Focusing works via a twist ring on the eyepiece. Easy focusing in the foreground and background without moving the endoscope. Bright, colour-corrected bar optics.

#### Suitable for :

FlexiVision 100 with HD camera head No. 492866.

#### Optional extras:

LED light sources No. 492846 and No. 462860.

#### Note:

Using slip-on mirror sleeves the direction of view can be changed to 70° or 90°. When mirror sleeves are used the working diameter increases according to the mirror sleeve. Mirror sleeves and exchangeable lenses available on request.

Direction of view: 0°

Image aperture angle: 85°

### Technical description

Direction of view	0°
Image aperture angle	85°

Working length (without lens)	1000 mm
Probe Ø	2.4 mm
Product name attribute	Ø 2.4 mm
Type of product	Endoscope