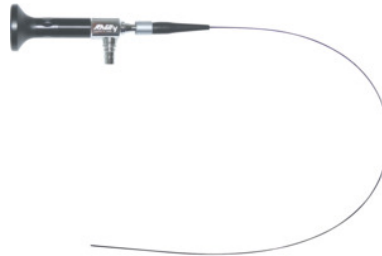


**Flexible micro-endoscope, Ø 1.9 mm, Working length (without lens): 1000mm****Order data**

Order number	492756 1000
GTIN	
Item class	49C

Description**Version:**

The sturdy stainless steel tube and high-quality optics are specially well suited for rough industrial environments. Easy to connect to the required light source for the standard fibre optic cable connection (ACMI). Focusing works via a twist ring on the eyepiece. Easy focusing in the foreground and background without moving the endoscope. Bright, colour-corrected bar optics. Small diameter and flexible fibre optic design for measuring very fine components.

Suitable for:

FlexiVision 100 with HD camera head No. 492866.

Optional extras:

LED light sources No. 492846 and No. 462860.

Note:

Using slip-on mirror sleeves the direction of view can be changed to 70° or 90°. When mirror sleeves are used the working diameter increases according to the mirror sleeve. Mirror sleeves and exchangeable lenses available on request.

Technical description

Image aperture angle	85 °
Direction of view	0 °
Working length (without lens)	1000 mm

Probe Ø	1.9 mm
Product name attribute	Ø 1.9 mm
Type of product	Endoscope