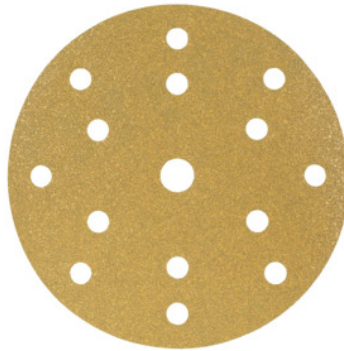


Garant**Velour-backed abrasive disc (A) 15 holes, Ø 150 mm, Grit: 400****Order data**

Order number	567553 400
GTIN	4062406297671
Item class	51M

Description**Version:**

Velour-backed abrasive disc with **paper backing**. Dust-repellent coating prevents premature clogging. The back is covered with velour loops.

Velour-backed abrasive disc with open distribution, aluminium oxide (A). Ideally suited to materials that have a high tendency to clogging.

Application:

On **orbital sanders** with hook and loop pads e.g.No. 567990 (dust extraction available).

Universal **all-round product** for coarse, intermediate and fine abrasion on all metal and plastic surfaces, paint systems and woods.

Technical description

Disc Ø	150 mm
Grit	400
Grinding media	Aluminium Oxide grit (A)
Grinding medium code	A

Iron, sulphur and chlorine constituents	< 0.1 %
Product name attribute	Ø 150 mm
Number of dust extraction holes	15
Propulsive equipment	Orbital sander
maximum circumferential speed	40 m/s
Type of product	Velour-backed abrasive disc

User data

	Suitability	V _c	ISO code
Alu Mg	suitable		
Steel < 900 N/mm ²	suitable		
Steel < 1400 N/mm ²	suitable		
Steel < 55 HRC	suitable		
Steel < 60 HRC	suitable		
Steel < 67 HRC	suitable only under restricted conditions		
INOX	suitable		
Ti	suitable only under restricted conditions		
CuZn	suitable		
Plastic, GRP	suitable		
Wood	suitable		
Paint	suitable		
Uni	suitable		
dry	suitable		