


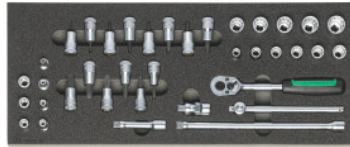

## Socket set 3/8 inch, Number of tools: 37



### Order data

Order number	953748 37
GTIN	2050002043015
Item class	91A

### Description

#### Version:

Popular tool sets in two-colour moulded PE rigid foam inlays. The closed-pore foam is oil-resistant and does not absorb liquids of any sort. **Upper layer is anthracite**, the underlying **contrast colour is grey**, thereby indicating any missing tools.

#### Supplied with:

Rigid foam inlay No. 952001 size 953748: 1 pc.

STAHLWILLE bi-hex socket 3/8 inch No. 637000 size 8; 10; 11; 12; 13; 14; 15; 16; 17; 18; 19: 1 pc. each

STAHLWILLE hexagon screwdriver bit 3/8 inch No. 637600 size 4; 5; 6; 7; 8; 10: 1 pc. each

STAHLWILLE socket 3/8 inch No. 637450 size E5; E6; E7; E8; E10; E12; E14: 1 pc. each

STAHLWILLE socket 3/8 inch No. 637560 size TX9; TX10; TX15; TS20; TX 25; TX27; TX30; TX40: 1 pc. each

STAHLWILLE reversible ratchet, 3/8 inch No. 635000 size 3/8: 1 pc.

STAHLWILLE extension No. 635400 size 75; 240: 1 pc. each

STAHLWILLE T-handle No. 635700 size 165: 1 pc.

STAHLWILLE universal joint No. 636200 size 3/8: 1 pc.

### Technical description

Depth in G	20
Width in G	8
Depth	500 mm
Weight	1.962 kg

Width	200 mm
Number of tools	37
Version	with socket
Rigid foam quality LD45, thickness	30 mm
Degree of fill of a drawer in units	8x20
Square drive	3/8 in
Type of product	Rigid foam inlay

## Accessories

Screwdriver socket, for Torx®, 3/8 inch short Torx® profile TX15	637560 TX15
Screwdriver socket, for Torx®, 3/8 inch short Torx® profile TX20	637560 TX20
Bi-hexagon socket, 3/8 inch Width across flats 16 mm	637000 16
Reversible ratchet, 3/8 inch Type 3/8	635000 3/8
Screwdriver socket, hexagon, 3/8 inch Hexagon 6 mm	637600 6
Bi-hexagon socket, 3/8 inch Width across flats 13 mm	637000 13
Screwdriver socket, for Torx®, 3/8 inch short Torx® profile TX10	637560 TX10
Bi-hexagon socket, 3/8 inch Width across flats 11 mm	637000 11
Screwdriver socket, hexagon, 3/8 inch Hexagon 7 mm	637600 7
Bi-hexagon socket, 3/8 inch Width across flats 19 mm	637000 19
Screwdriver socket, hexagon, 3/8 inch Hexagon 5 mm	637600 5
Bi-hexagon socket, 3/8 inch Width across flats 15 mm	637000 15
Socket, 3/8 inch for Torx® Torx® profile E14	637450 E14
Bi-hexagon socket, 3/8 inch Width across flats 17 mm	637000 17
Socket, 3/8 inch for Torx® Torx® profile E12	637450 E12
Socket, 3/8 inch for Torx® Torx® profile E7	637450 E7
Bi-hexagon socket, 3/8 inch Width across flats 18 mm	637000 18

Screwdriver socket, for Torx®, 3/8 inch short Torx® profile TX40	637560 TX40
Bi-hexagon socket, 3/8 inch Width across flats 9 mm	637000 9
Extension, 3/8 inch overall length 240 mm	635400 240
Universal joint, 3/8 inch Type 3/8	636200 3/8
Socket, 3/8 inch for Torx® Torx® profile E8	637450 E8
Bi-hexagon socket, 3/8 inch Width across flats 8 mm	637000 8
Screwdriver socket, for Torx®, 3/8 inch short Torx® profile TX27	637560 TX27
Socket, 3/8 inch for Torx® Torx® profile E5	637450 E5
Bi-hexagon socket, 3/8 inch Width across flats 12 mm	637000 12
Screwdriver socket, for Torx®, 3/8 inch short Torx® profile TX30	637560 TX30
Bi-hexagon socket, 3/8 inch Width across flats 14 mm	637000 14
Bi-hexagon socket, 3/8 inch Width across flats 10 mm	637000 10
Screwdriver socket, for Torx®, 3/8 inch short Torx® profile TX9	637560 TX9
Screwdriver socket, for Torx®, 3/8 inch short Torx® profile TX25	637560 TX25
T-handle, 3/8 inch overall length 165 mm	635700 165
Socket, 3/8 inch for Torx® Torx® profile E10	637450 E10
Screwdriver socket, hexagon, 3/8 inch Hexagon 4 mm	637600 4
Rigid foam inlay for tool sets suitable for rigid foam set 953748	952001 953748
Socket, 3/8 inch for Torx® Torx® profile E6	637450 E6
Extension, 3/8 inch overall length 75 mm	635400 75
Screwdriver socket, hexagon, 3/8 inch Hexagon 10 mm	637600 10
Screwdriver socket, hexagon, 3/8 inch Hexagon 8 mm	637600 8