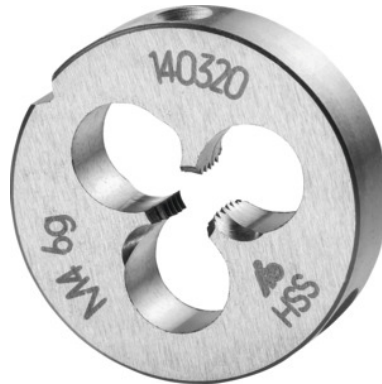


**HOLEX®**
**Die 6g, M: M4**

**Order data**

Order number	140320 M4
GTIN	4045197083265
Item class	12K

**Description**
**Version:**

Closed, pre-slit form. **≥ M3 with tapered lead chamfer** on both sides for easy start to the threading action and clean swarf evacuation in the direction of cutting. **1¾ turns lead chamfer.**

Thread type: M

Flank angle: 60 degrees

Tool material: HSS

Norm: EN 22568

Tolerance class: DIN 13 6g

Pitch: 0.7 mm

External Ø: 20 mm

Height: 5 mm

**Technical description**

Height	5 mm
Pitch	0.7 mm
External Ø	20 mm

Tolerance class	DIN 13 6g
Thread size	4
Thread type	M
Flank angle	60 degrees
Tool material	HSS
Norm	EN 22568
Cutting direction	right-hand