


PRYOR

**Interchangeable numeral and letter punch set normal script 0 - 9 and A - Z,
Character height: 2mm**

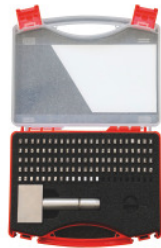

Order data

Order number	085480 2
GTIN	5022044020283
Item class	08W

Description

Version:

High precision punch holder for quick and efficient marking with **several letters and numbers at the same time.**

Application:

For punching into materials (e.g. identification plates, tools, machine parts etc.) with **strengths up to 1200 N/mm².**

Supplied with:

100 stamp types
12 spacers (font height 5 mm: 6 pieces)
1 pair of tweezers
1 hexagon L-wrench
1 holder
in a plastic box.

Spare part:

Individual type punches can be ordered under No. 085481 stating the desired font size / type (e.g. No. 085481 size 3/E).

Technical description

Number of punch types that can be used	14
Length of punch type	19.05 mm
Height of punch type	6.4 mm
Length of punch holder	29 mm
Width of punch type	2 mm
Character height	2 mm
Type of product	Hand punch

Accessories

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/X mm	085481 2/X
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/I mm	085481 2/I
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/T mm	085481 2/T
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/. mm	085481 2/.
Interchangeable steel type punches Numbers range 0 – 9 Character height 2 mm	085483 2
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/Q mm	085481 2/Q
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/K mm	085481 2/K
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2// mm	085481 2//
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/7 mm	085481 2/7
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/B mm	085481 2/B
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2LEER mm	085481 2LEER

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/P mm	085481 2/P
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/O mm	085481 2/O
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/A mm	085481 2/A
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/, mm	085481 2/,
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/R mm	085481 2/R
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/L mm	085481 2/L
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/1 mm	085481 2/1
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/& mm	085481 2/&
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/F mm	085481 2/F
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/D mm	085481 2/D
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/- mm	085481 2/-
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/2 mm	085481 2/2
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/S mm	085481 2/S
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/J mm	085481 2/J
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/6 mm	085481 2/6
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/W mm	085481 2/W
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/U mm	085481 2/U
	085481 2/M

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/M mm

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/Y mm

085481 2/Y

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/4 mm

085481 2/4

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/H mm

085481 2/H

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/G mm

085481 2/G

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/0 mm

085481 2/0

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/8 mm

085481 2/8

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/9 mm

085481 2/9

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/+ mm

085481 2/+

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/Z mm

085481 2/Z

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/3 mm

085481 2/3

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/V mm

085481 2/V

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/C mm

085481 2/C

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/E mm

085481 2/E

Steel type holder individual for set No. 085480 suitable for font 2-3 mm

085482 2-3

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/N mm

085481 2/N

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 2/5 mm

085481 2/5