


PRYOR

**Interchangeable numeral and letter punch set normal script 0 - 9 and A - Z,
Character height: 3mm**

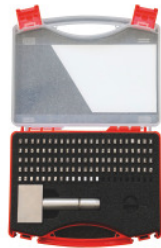

Order data

Order number	085480 3
GTIN	5022044020153
Item class	08W

Description

Version:

High precision punch holder for quick and efficient marking with **several letters and numbers at the same time.**

Application:

For punching into materials (e.g. identification plates, tools, machine parts etc.) with **strengths up to 1200 N/mm².**

Supplied with:

100 stamp types
12 spacers (font height 5 mm: 6 pieces)
1 pair of tweezers
1 hexagon L-wrench
1 holder
in a plastic box.

Spare part:

Individual type punches can be ordered under No. 085481 stating the desired font size / type (e.g. No. 085481 size 3/E).

Technical description

Width of punch type	3.2 mm
Length of punch holder	29 mm
Number of punch types that can be used	9
Length of punch type	19.05 mm
Character height	3 mm
Height of punch type	6.4 mm
Type of product	Hand punch

Accessories

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 3/+ mm	085481 3/+
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 3/8 mm	085481 3/8
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 3/T mm	085481 3/T
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 3/Y mm	085481 3/Y
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 3/F mm	085481 3/F
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 3/& mm	085481 3/&
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 3/M mm	085481 3/M
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 3/H mm	085481 3/H
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 3/N mm	085481 3/N
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 3/V mm	085481 3/V
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 3/U mm	085481 3/U

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 3// mm	085481 3//
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 3/R mm	085481 3/R
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 3/D mm	085481 3/D
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 3/, mm	085481 3/,
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 3/2 mm	085481 3/2
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 3/A mm	085481 3/A
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 3/K mm	085481 3/K
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 3/l mm	085481 3/l
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 3/E mm	085481 3/E
Steel type holder individual for set No. 085480 suitable for font 2-3 mm	085482 2-3
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 3/B mm	085481 3/B
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 3/O mm	085481 3/O
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 3/0 mm	085481 3/0
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 3/Q mm	085481 3/Q
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 3/S mm	085481 3/S
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 3/6 mm	085481 3/6
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 3/7 mm	085481 3/7
	085483 3

Interchangeable steel type punches Numbers range 0 – 9
Character height 3 mm

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 3/5 mm

085481 3/5

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 3/3 mm

085481 3/3

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 3/W mm

085481 3/W

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 3/4 mm

085481 3/4

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 3/X mm

085481 3/X

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 3/- mm

085481 3/-

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 3/1 mm

085481 3/1

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 3/Z mm

085481 3/Z

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 3/. mm

085481 3/.

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 3/G mm

085481 3/G

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 3LEER mm

085481 3LEER

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 3/J mm

085481 3/J

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 3/L mm

085481 3/L

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 3/C mm

085481 3/C

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 3/P mm

085481 3/P

Steel type punches individually exchangeable, for set No.
085480 Character height / Characters 3/9 mm

085481 3/9