


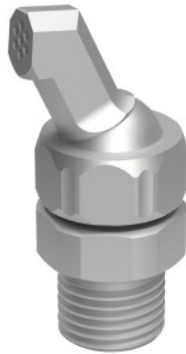

## HighPressure coolant nozzle angled 60°, Thread: M10X1



### Order data

Order number	319475 M10X1
GTIN	2050002048218
Item class	33C

### Description

#### Version:

For targeted cooling and lubrication on the cutting edge/evacuation of chips.

**High-pressure nozzle** – specially designed for high pressures up to 80 bar. Adjustable nozzle angle position. Sturdy and durable version made of aluminium.

60° angled nozzle, multi-hole version 7 (holes) × dia. 1 mm.

#### Application:

For use on static and driven toolholders via a threaded connector.

### Technical description

Type	angled
Version	Thread
Connection thread	M10×1
Pipe feed-through Ø	1 mm
Through-coolant	yes
Type of product	Coolant nozzle

