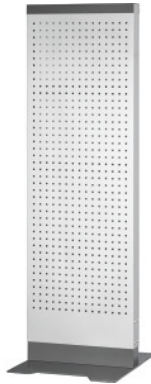


Garant UNILINE

UNI Wall stationary, Type: M**Order data**

Order number	955450 M
GTIN	4062406584597
Item class	9GC

Description**Version:**

Very sturdy double-walled column made from sheet metal, perforated panels that can be used on both sides □ 9×9 mm on a 37 mm grid for attaching perforated panel accessories and Easyfix hooks and holders. Sturdy base plate in anthracite permits easy set up and movement.

Colour:

Two-tone **powder-coated**, silver combined with anthracite RAL 7016. **Not configurable.**

Note:

See No. 955453 for marking attachment. Suitable pictograms (various application purposes) for marking attachment can be found under No. 955474.

Technical description

Height	1920 mm
Width	600 mm
Safe working load	75 kg
Usable width	600 mm
Depth	750 mm

Series	Wall
Hoffmann perforated panel grid interval	9×9
Type of product	Perforated panel stand