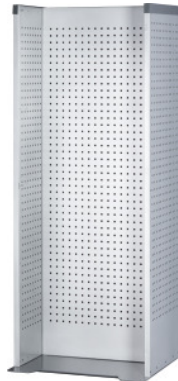


Garant UNILINE

**UNI Tower stationary H-shape, Type: L****Order data**

Order number	955461 L
GTIN	4062406584696
Item class	9GC

**Description****Version:**

Presentable modular provision system for direct access to work materials and quick visualisation of information. Freely configurable due to a wide variety of accessories and perfect compatibility with the Easyfix system. Versatile and general-purpose use for various different applications and fittings, e.g. for 5S implementation, provision of first aid materials, cleaning materials, tools, information, etc.

All sides inside and outside with perforated panels  $\square 9 \times 9$  mm on a 37 mm grid for attaching perforated panel accessories and Easyfix hooks and holders. Can be identified quickly in the production area due to optional signal attachments. Optional lockable doors offer the facility for secure storage. H shape: 2 side walls with central cross panel. Storage shelves and doors can be fitted on the front and rear. Drawers cannot be fitted.

**Colour:**

Two-tone **powder-coated**, silver combined with RAL 7016 anthracite. **Not configurable.**

**Note:**

Accessories such as attachments, pictograms, storage shelves, drawers, doors and push handles can be found under No. 955474 – 955499.

**Technical description**

Width	750 mm
Safe working load	150 kg
Weight	92 kg
Series	Tower
Usable width	690 mm
Depth	750 mm
Usable depth	2 × 255 mm
Height	1920 mm
Hoffmann perforated panel grid interval	9 × 9
Height adjustment interval	37
Type of product	Perforated panel tower