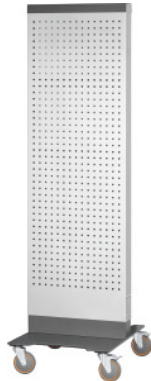


Garant UNI LINE**UNI Wall mobile, Type: M****Order data**

Order number	955451 M
GTIN	4062406584719
Item class	9GC

Description**Version:**

Very sturdy double-walled column made from sheet metal, perforated panels that can be used on both sides \square 9x9 mm on a 37 mm grid for attaching perforated panel accessories and Easyfix hooks and holders. Sturdy base plate in anthracite permits easy set up and movement. With 4 castors, \varnothing 125 mm, 2 with parking brake.

Colour:

Two-tone **powder-coated**, silver combined with anthracite RAL 7016. **Not configurable.**

Note:

See No. 955453 for marking attachment. Suitable pictograms (various application purposes) for marking attachment can be found under No. 955474.

Technical description

Width	600 mm
Height	2067 mm
Series	Wall
Wheel \varnothing	125 mm

Usable width	600 mm
Depth	750 mm
Safe working load	75 kg
Weight	69 kg
Hoffmann perforated panel grid interval	9×9
Type of product	Perforated panel stand

Accessories

Set of wheels for UNI Line, 4 pieces Type 1	955459 1
UNI Wallstationary Type M	955450 M