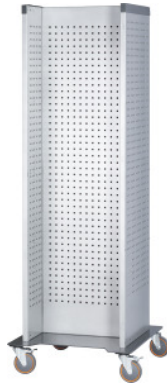


Garant UNI LINE**UNI Tower mobile H-shape, Type: M****Order data**

Order number	955463 M
GTIN	4062406584740
Item class	9GC

Description**Version:**

Presentable modular provision system for direct access to work materials and quick visualisation of information. Freely configurable due to a wide variety of accessories and perfect compatibility with the Easyfix system. Versatile and general-purpose use for various different applications and fittings, e.g. for 5S implementation, provision of first aid materials, cleaning materials, tools, information, etc.

All sides inside and outside with perforated panels $\square 9 \times 9$ mm on a 37 mm grid for attaching perforated panel accessories and Easyfix hooks and holders. Can be identified quickly in the production area due to optional signal attachments. Optional lockable doors offer the facility for secure storage. With 4 castors, $\varnothing 125$ mm, 2 with parking brake.

H shape: 2 side walls with central cross panel. Storage shelves and doors can be fitted on the front and rear. Drawers cannot be fitted.

Colour:

Two-tone **powder-coated**, silver combined with RAL 7016 anthracite. **Not configurable.**

Note:

Accessories such as attachments, pictograms, storage shelves, drawers, doors and push handles can be found under No. 955474 – 955499.

Technical description

Depth	750 mm
Weight	89 kg
Wheel Ø	125 mm
Series	Tower
Height	2070 mm
Usable width	540 mm
Usable depth	2 × 255 mm
Safe working load	150 kg
Width	720 mm
Hoffmann perforated panel grid interval	9×9
Height adjustment interval	37
Type of product	Perforated panel tower

Accessories

Set of wheels for UNI Line, 4 pieces Type 1	955459 1
UNI Towerstationary H-shape Type M	955461 M