


Garant UNILINE

UNI Tower H-shape asymmetrical fixed, Type: L

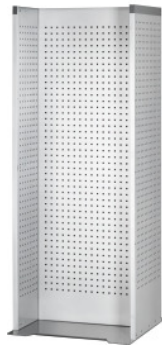

Order data

Order number	987104 L
GTIN	4062406587888
Item class	9GC

Description

Version:

Modular provision system for direct access to work materials and quick visualisation of information.

The UNI Tower H-shape can be **equipped from both sides**. 2 recycling collection bins No. 987110 size 45 can be accommodated in a lower compartment. The smaller compartment is suitable for storing cleaning agents and equipment.

Freely configurable due to a wide variety of accessories and perfect compatibility with the Easyfix system. All outer walls and the centre partition have perforated panels on all sides $\square 9 \times 9$ mm on a 37 mm grid for attaching perforated panel accessories and Easyfix hooks and holders. Anthracite-coloured attachment with cleaning pictogram provides quick visualisation. Optional lockable doors offer the facility for secure storage. The door cannot be combined in conjunction with a paper roll holder.

Colour:

Two-tone **powder-coated**, silver combined with anthracite RAL 7016. **Not configurable.**

Note:

Further accessories such as pictograms, storage shelves, drawers and doors can be found under No. 955474 – 955499.

Hoffmann perforated panel grid interval: 9×9

Height: 1920 mm

Width: 750 mm

Depth: 750 mm
Usable width: 690 mm
Usable depth: 180/ 330 mm
Weight: 92 kg

Technical description

Width	750 mm
Usable depth	180/ 330 mm
Height	1920 mm
Series	Tower
Weight	92 kg
Usable width	690 mm
Depth	750 mm
Hoffmann perforated panel grid interval	9×9
Type of product	Cleaning station