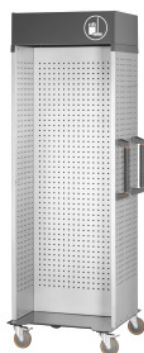


Garant **UNI LINE****CLEANING Tower, H-shape mobile, Type: L****Order data**

Order number	987103 L
GTIN	4062406588922
Item class	9GC

**Description****Version:**

Modular cleaning tower for direct access to cleaning devices. The asymmetrical CLEANING Tower H-shape can **equipped from both sides**. Up to 4 recycling collection bins No. 987125 size 25 can be accommodated in a lower compartment. The smaller compartment is suitable for storing cleaning agents and equipment.

Freely configurable due to a wide variety of accessories and perfect compatibility with the Easyfix system. All outer walls and the centre partition have perforated panels on all sides □ 9×9 mm on a 37 mm grid for attaching perforated panel accessories and Easyfix hooks and holders. Anthracite-coloured attachment with cleaning pictogram provides quick visualisation. Optional lockable doors in size L offer the facility for secure storage. The door cannot be combined in conjunction with a paper roll holder.

**Supplied with:**

CLEANING Tower H-shape asymmetric; attachment No. 955476 size L; 2 pcs. push handle No. 955496 size 1.

With 4 castors, Ø 125 mm, 2 with parking brake.

**Colour:**

Two-tone **powder-coated**, silver combined with anthracite RAL 7016. **Not configurable.**

**Technical description**

Usable depth	180/ 330 mm
Height	2290 mm
Safe working load	150 kg
Series	CLEANING Tower UNI Line
Width	750 mm
Usable width	690 mm
Wheel Ø	125 mm
Weight	96 kg
Depth	750 mm
Hoffmann perforated panel grid interval	9×9
Type of product	Cleaning station

---

## Accessories

Attachment for UNI Tower L Type GREY	955476 GREY
Set of wheels for UNI Line, 4 pieces Type 1	955459 1
CLEANING Tower, H-shape stationary Type L	987102 L
UNI Line push handle Type 1	955496 1
UNI Line pictogram Type CLEANING	955474 CLEANING