


Garant GRIDLINE

Large-capacity / heavy-duty cabinet with Viewing window sliding door, Height: 900mm

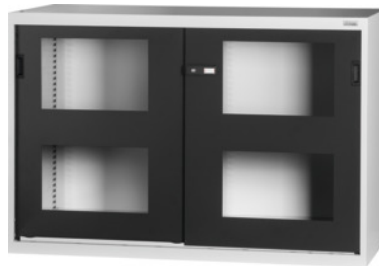

Order data

Order number	942747 900
GTIN	4062406595890
Item class	9GI

Description

Version:

Empty cabinet in 60×28G. Suitable drawers: 26×20G (please order these separately). Mountings for shelves at 25 mm intervals. Doors reinforced on the inside and can be locked by 2-component Haptoprene® handle using a cylinder lock.

Colour:

Body RAL 7035 light grey, doors RAL 7016 anthracite **powder-coated**.

Note:

For storage shelves and accessories for GridLine large-capacity cabinets and heavy-duty cabinets see No. 942530 – 942610 and Group 95.

Use as a heavy-duty cabinet is only possible in conjunction with heavy load shelf No. 942610.

According to the TÜV GS certification, it is essential that all cabinets are secured against tipping over.

Technical description

Type of cabinet	Base cabinet
ComfortClose	no
Electronic locking system can be retrofitted	yes
Weight	113 kg

Cabinet fronts	Viewing window sliding door
Handle positioning	top
Width in G	60
Height	900 mm
Depth in G	28
Depth	700 mm
Usable height	763 mm
Width	1500 mm
Version	for individual configuration
Material thickness	0.9 mm
Cabinet housing internal load capacity	1600
Height adjustment interval	25
Cylinder lock	modular barrel
Colour selection	RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003
Type of product	Large-capacity cabinet

Accessories

Lock plate for GridLine Type GP21	914227 GP21
-----------------------------------	-------------