


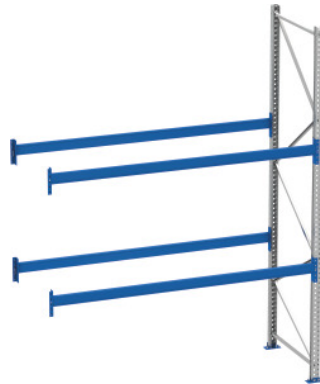

Pallet add-on rack, Depth 1100 mm, Height: 3600mm



Order data

Order number	992415 3600
GTIN	4052941835834
Item class	95S

Description

Version:

Pallet racking made of cold-rolled high-strength steel profile frame. High stiffness of the frame due to special design: Bolted to a sturdy framework with horizontal and diagonal struts. Longitudinal crossbeams with welded-on 5-hook suspension brackets for a positive and frictional connection with rack supports. Including floor anchors.

Supplied with:

Basic rack: 2 profile frames, longitudinal cross beams, 8 floor anchors, 2 safe working load signs.

Extension rack: 1 profile frame, longitudinal cross beams, 4 floor anchors.

Colour:

Stiles galvanised, beams RAL 5010 gentian blue **powder-coated**.

Note:

- **On uneven floors we recommend additional shim plates.**
- **Supplied for self-assembly, saving freight costs. Delivered unassembled.**

Type of installation: Plug-in racking

Compartment width: 2700 mm

Cross beam height: 100 mm

lower compartment height: 1500 mm

Number of longitudinal cross beams: 4

Number of storage level: 2

maximum bay load: 4800 kg

Technical description

Width	2700 mm
Application range	Pallet racking
Depth	1100 mm
Number of storage level	2
Height	3600 mm
Compartment width	2700 mm
maximum bay load	4800 kg
Number of longitudinal cross beams	4
Cross beam height	100 mm
lower compartment height	1500 mm
Shelf load capacity / maximum distributed shelf load (on metal)	2400 kg
To take pallets with load capacity	800 kg
Height adjustment interval	50 mm
Type of installation	Plug-in racking
Product name attribute	Depth 1100 mm
Type of product	Pallet racking

Accessories

Pair of longitudinal cross beams Width 2700 mm	992482 2700
Floor anchor Number of floor anchors 2	992545 2
Frame stiles Height 3600 mm	992461 3600
Locking pins, 12 pieces Number of locking pins 12	992501 12