


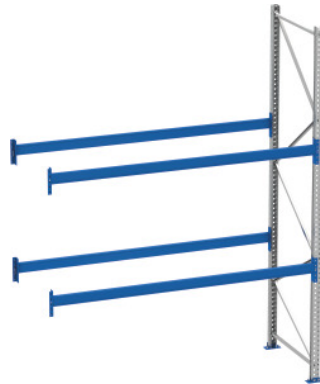

Pallet add-on rack, Depth 1100 mm, Height: 3600mm



Order data

Order number	992425 3600
GTIN	4052941835889
Item class	95S

Description

Version:

Pallet racking made of cold-rolled high-strength steel profile frame. High stiffness of the frame due to special design: Bolted to a sturdy framework with horizontal and diagonal struts. Longitudinal crossbeams with welded-on 5-hook suspension brackets for a positive and frictional connection with rack supports. Including floor anchors.

Supplied with:

Basic rack: 2 profile frames, longitudinal cross beams, 8 floor anchors, 2 safe working load signs.

Extension rack: 1 profile frame, longitudinal cross beams, 4 floor anchors.

Colour:

Stiles galvanised, beams RAL 5010 gentian blue **powder-coated**.

Note:

- **On uneven floors we recommend additional shim plates.**
- **Supplied for self-assembly, saving freight costs. Delivered unassembled.**

Type of installation: Plug-in racking

Compartment width: 2700 mm

Cross beam height: 110 mm

lower compartment height: 1500 mm

Number of longitudinal cross beams: 4

Number of storage level: 2

maximum bay load: 6000 kg

Technical description

Width	2700 mm
Height	3600 mm
Compartment width	2700 mm
Number of storage level	2
Depth	1100 mm
Application range	Pallet racking
maximum bay load	6000 kg
Number of longitudinal cross beams	4
lower compartment height	1500 mm
Cross beam height	110 mm
Shelf load capacity / maximum distributed shelf load (on metal)	3000 kg
To take pallets with load capacity	1000 kg
Height adjustment interval	50 mm
Type of installation	Plug-in racking
Product name attribute	Depth 1100 mm
Type of product	Pallet racking

Accessories

Locking pins, 12 pieces Number of locking pins 12	992501 12
Frame stiles Height 3600 mm	992464 3600
Floor anchor Number of floor anchors 2	992545 2
Pair of longitudinal cross beams Width 2700 mm	992485 2700